 


Hydraulic Fittings


Straight / 45° Elbow / Elbow

PT/PF, Male Threads
Long Straight Male




RoHS 10

Type	Material	Surface Treatment
YCLPLF	S35C	Trivalent Chromate

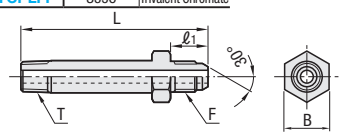


Part Number	T	F	L	l ₁	B	Unit Price
Type	No.	R (PT)	G (PF)			YCLPLF
22F	1/4	1/4	74	16	19	
33F	3/8	3/8	80	18	22	
44F	1/2	1/2	95	20	27	

PT/PF, Male Threads
45° Elbow Male




RoHS 10

Type	Material	Surface Treatment
YCWPF	S25C	Trivalent Chromate
YCWPFPS	SUS304	-

 


Part Number	T	F	L ₁	L ₂	l ₁	l ₂	Unit Price
Type	No.	R (PT)	G (PF)				YCWPF YCWPFPS
11F	1/8	1/8	19	19	12	13	
22F	1/4	1/4	20	22	13	16	
33F	3/8	3/8	23	26	15	18	
44F	1/2	1/2	28	29	18	20	

PT/PT, Male Threads
Elbow




RoHS 10

Type	Material	Surface Treatment
YCLPT	S25C	Trivalent Chromate
YCLPTS	SUS304	-

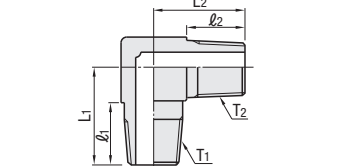


Part Number	T ₁	T ₂	L ₁	L ₂	l ₁	l ₂	Unit Price
Type	No.	R (PT)	R (PT)				YCLPT YCLPTS
11	1/8	1/8	20	20	13	13	
12	1/8	1/4	20	24	13	16	
13	1/8	3/8	20	27	13	17	
22	1/4	1/4	24	24	16	16	
23	1/4	3/8	24	27	16	17	
33	3/8	3/8	27	27	17	17	
34	3/8	1/2	30	30	17	18	
44	1/2	1/2	30	30	19	19	
66	3/4	3/4	36	36	23	23	

PT/PF, Male Threads
Elbow Male




RoHS 10

Type	Material	Surface Treatment
YCLPFP	S25C	Trivalent Chromate
YCLPFPFS	SUS304	-

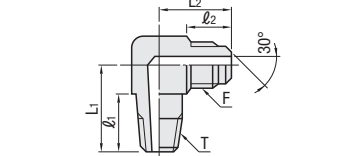


Part Number	T	F	L ₁	L ₂	l ₁	l ₂	Unit Price
Type	No.	R (PT)	G (PF)				YCLPFP YCLPFPFS
11F	1/8	1/8	21	20	14	13	
12F	1/8	1/4	22	24	14	16	
21F	1/4	1/8	22	21	15	13	
22F	1/4	1/4	25	24	17	16	
23F	1/4	3/8	27	27.5	17	17.5	
32F	3/8	1/4	30	26	20	16	
33F	3/8	3/8	30	27.5	20	17.5	
34F	3/8	1/2	32	32	20	20	
44F	1/2	1/2	36	32	24	20	
46F	1/2	3/4	38	36	24	22	
64F	3/4	1/2	42	34	28	20	
66F	3/4	3/4	43	37	28	22	

PT/PF, Male Threads
45° Elbow Female




RoHS 10

Type	Material	Surface Treatment
YCWPF	S25C	Trivalent Chromate
YCWPFPS	SUS304	-

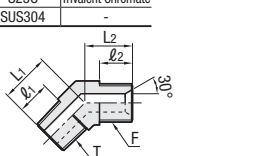


Part Number	T	F	L ₁	L ₂	l ₁	l ₂	Unit Price
Type	No.	R (PT)	G (PF)				YCWPF YCWPFPS
11F	1/8	1/8	18	17	12	11	
22F	1/4	1/4	21	21	13	13	
33F	3/8	3/8	23	23	15	15	
44F	1/2	1/2	29	28	18	18	

PT/PT, Male Threads
45° Elbow




RoHS 10

Type	Material	Surface Treatment
YCWPT	S25C	Trivalent Chromate

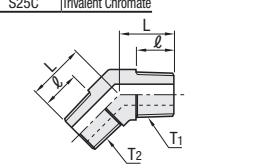


Part Number	T ₁	T ₂	L	l	Unit Price
Type	No.	R (PT)	R (PT)		YCWPT
11	1/8	1/8	17	12	
22	1/4	1/4	19	14	
33	3/8	3/8	22	15	
44	1/2	1/2	28	18	

PT/PF, Female Threads
Elbow Female




RoHS 10

Type	Material	Surface Treatment
YCLPF	S25C	Trivalent Chromate
YCLPFS	SUS304	-

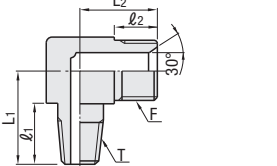


Part Number	T	F	L ₁	L ₂	l ₁	l ₂	Unit Price
Type	No.	R (PT)	G (PF)				YCLPF YCLPFS
11F	1/8	1/8	21	18	14	11	
12F	1/8	1/4	22	21	14	13	
13F	1/8	3/8	24	25	14	15	
21F	1/4	1/8	22	19	15	11	
22F	1/4	1/4	25	21	17	13	
23F	1/4	3/8	27	25	17	15	
31F	3/8	1/8	30	21	20	11	
32F	3/8	1/4	30	23	20	13	
33F	3/8	3/8	30	25	20	15	
34F	3/8	1/2	32	30	20	18	
44F	1/2	1/2	36	30	24	18	
46F	1/2	3/4	38	34	24	20	
64F	3/4	1/2	42	32	28	18	
66F	3/4	3/4	43	35	28	20	

PT/PF, Female Threads
Elbow Male



RoHS 10

Type	Material	Surface Treatment
YCLPFG	S25C	Trivalent Chromate

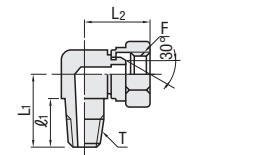

Part Number	T	F	L ₁	L ₂	l ₁	Unit Price
Type	No.	R (PT)	G (PF)			YCLPFG
22F	1/4	1/4	25	28	17	
33F	3/8	3/8	30	33	20	

Ordering Example **Part Number**
YCLPT11

Specifications Applicable Fluids : Oil, Water
Max. Operating Pressure : 20.6MPa (210kgf/cm² or less)