
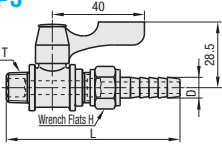

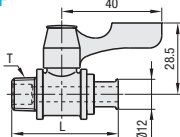

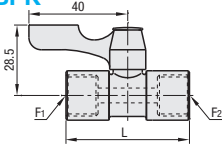

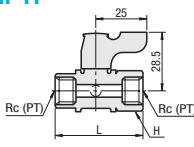

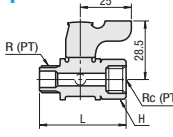



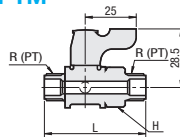

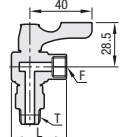

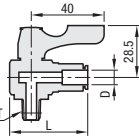
Compact Ball Valves

Straight / Elbow

☞ The photo shows "open" status. Close condition can be obtained by counterclockwise rotation of 90°.

<p>Straight PT Male / Hose Connection</p> 	<p>BBPJ</p> 
<p>Straight PT Male / Peacock</p> 	<p>BBPP</p> 
<p>Straight PF / PF Female Metric Valve</p> 	<p>BBPK</p> 
<p>Straight PT / PT Female</p> 	<p>BBRPTF</p> 
<p>Straight PT Male / PT Female</p> 	<p>BBRPT</p> 

Ordering Example **Part Number**
BBPJ628

<p>Straight PT / PT Male</p> 	<p>BBRPTM</p> 
<p>Elbow PT Male / PF Female</p> 	<p>BBPTL</p> 
<p>Elbow PT Male / Tube Connection</p> 	<p>BBPCL</p> 

Ordering Example **Part Number** - **Color**
BBPTL11F - B



Specifications

Applicable Fluids	Water, Air, Oil
Operating Temperature Range	-10 ~ 80°C (No Freezing)
Normal Operating Pressure	0.98MPa

Part Number Type	No.	Applicable Hose I.D. (mm)		T R (PT)	D	L	Wrench Flats H	Unit Price	Volume Discount Rate
		1 ~ 4 pc(s)	5 ~ 10 pcs.						
BBPJ	628	6	1/4	8	75	16			
	629	6	1/4	9					
	93	9	3/8	10.5					

☞ For orders larger than indicated quantity, please check with WOS.

Part Number Type	No.	T R (PT)		L	Unit Price	Volume Discount Rate
		1 ~ 4 pc(s)	5 ~ 10 pcs.			
BBPP	11F	1/8	43			
	22F	1/4				
	33F	3/8				

☞ For orders larger than indicated quantity, please check with WOS.

Part Number Type	No.	F1 G (PF)		F2 G (PF)		L	Unit Price	Volume Discount Rate
		1 ~ 4 pc(s)	5 ~ 10 pcs.	1 ~ 4 pc(s)	5 ~ 10 pcs.			
BBPK	22F	1/4	1/4	50				
	33F	3/8	3/8					

☞ For orders larger than indicated quantity, please check with WOS.

Part Number Type	No.	Rc (PT)	L	Wrench Flats H	Unit Price	Volume Discount Rate
BBRPTF	11	1/8	43	17		
	22	1/4	43	17		
	33	3/8	55.5	22		

☞ For plumbing to the hex side, hold the valve's hex portion, not its body portion.

☞ For orders larger than indicated quantity, please check with WOS.

Part Number Type	No.	R (PT)	Rc (PT)	L	Wrench Flats H	Unit Price	Volume Discount Rate
BBRPT	11	1/8	1/8	43	17		
	22	1/4	1/4	43	17		
	33	3/8	3/8	55.5	22		

☞ For plumbing to the hex side, hold the valve's hex portion, not its body portion.

☞ For orders larger than indicated quantity, please check with WOS.

Part Number Type	No.	R (PT)	L	Wrench Flats H	Unit Price	Volume Discount Rate
BBRPTM	11	1/8	50	17		
	22	1/4	50			
	33	3/8	50			

☞ For plumbing to the hex side, hold the valve's hex portion, not its body portion.

☞ For orders larger than indicated quantity, please check with WOS.


Part Number Type	No.	Handle Color	T R (PT)	F G (PF)	L	Unit Price	Volume Discount Rate
BBPTL	11F	Not specified (Orange)	1/8	1/8	37		
	22F	B W (Black) (White) Y BL (Yellow) (Blue)	1/4	1/4	36		

☞ For orders larger than indicated quantity, please check with WOS.

Part Number Type	No.	Handle Color	D	T R (PT)	L	Unit Price	Volume Discount Rate
BBPCL	61	Not specified (Orange)	6	1/8	42.3		
	62			1/4			
	81	B W (Black) (White)		1/8			
	82	Y BL (Yellow) (Blue)		1/4			
	102			10			

☞ For orders larger than indicated quantity, please check with WOS.

Parts and Materials for Elbow Type

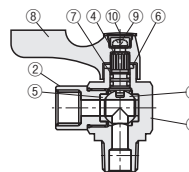

Part No.	Part Name	Material	Qty.
①	Body	Brass (Chrome Plating)	1
②	Socket	Brass (Chrome Plating)	1
③	Ball	Brass (Chrome Plating)	1
④	Stem	Brass	1
⑤	Seat	Fluororesin	2
⑥	Ring	Brass	1
⑦	O-Ring	Synthetic Rubber	2
⑧	Handle	Plastic	1
⑨	Screw	Steel	1
⑩	Caps	Plastic	1