
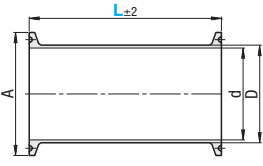

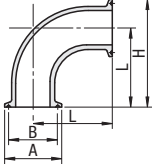

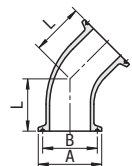

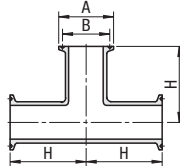

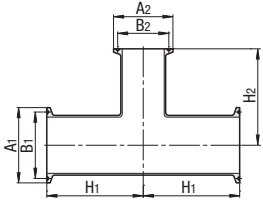


# Sanitary Pipe Fittings

## Double Ferrules

<b>Double Ferrules Straight</b>  <span style="color: green;">RoHS 10</span>	<table border="1"> <tr> <th>Type</th> <th>Material</th> </tr> <tr> <td>SNPAA</td> <td>SUS304</td> </tr> </table>	Type	Material	SNPAA	SUS304		
	Type	Material					
SNPAA	SUS304						
							
<b>Double Ferrules, Elbow</b>  <span style="color: green;">RoHS 10</span>	<table border="1"> <tr> <th>Type</th> <th>Material</th> </tr> <tr> <td>SNBE</td> <td>SUS304</td> </tr> <tr> <td>SNBES</td> <td>SUS316L</td> </tr> </table>	Type	Material	SNBE	SUS304	SNBES	SUS316L
	Type	Material					
SNBE	SUS304						
SNBES	SUS316L						
							
<b>Double Ferrules, 45° Elbow</b>  <span style="color: green;">RoHS 10</span>	<table border="1"> <tr> <th>Type</th> <th>Material</th> </tr> <tr> <td>SNBHE</td> <td>SUS304</td> </tr> <tr> <td>SNBHES</td> <td>SUS316L</td> </tr> </table>	Type	Material	SNBHE	SUS304	SNBHES	SUS316L
	Type	Material					
SNBHE	SUS304						
SNBHES	SUS316L						
							
<b>Double Ferrules, Tees</b>  <span style="color: green;">RoHS 10</span>	<table border="1"> <tr> <th>Type</th> <th>Material</th> </tr> <tr> <td>SNBT</td> <td>SUS304</td> </tr> <tr> <td>SNBTS</td> <td>SUS316L</td> </tr> </table>	Type	Material	SNBT	SUS304	SNBTS	SUS316L
	Type	Material					
SNBT	SUS304						
SNBTS	SUS316L						
							
<b>Double Ferrules, Reducing Tees</b>  <span style="color: green;">RoHS 10</span>	<table border="1"> <tr> <th>Type</th> <th>Material</th> </tr> <tr> <td>SNBTD</td> <td>SUS304</td> </tr> </table>	Type	Material	SNBTD	SUS304		
	Type	Material					
SNBTD	SUS304						
							

Part Number		L Selection	D	d	A	Unit Price 1 ~ 4 pc(s)			Volume Discount Rate 5 ~ 10 pcs.		
Type	No.					L100	L200	L250	L300	L100	L200
SNPAA	1S	100	25.4	23	50.5						
	1.5S	150	38.1	35.7	50.5						
	2S	200	50.8	47.8	64						

For orders larger than indicated quantity, please check with WOS.

Part Number		A	B	L	H	SNBE		SNBES	
Type	No.					Unit Price Qty. 1 ~ 9	Volume Discount Rate 10~20	Unit Price Qty. 1 ~ 9	Volume Discount Rate 10~20
SNBES	8A	34.0	27.5	55	72	-	-		
	10A					-	-		
	15A					-	-		
SNBE SNBES	1S	50.5	43.5	55	80.3				
	1.5S	50.5	43.5	70	95.3				
	2S	64.0	56.5	82	114				
	2.5S	77.5	70.5	105	143.8				
	3S	91.0	83.5	110	155.5				

For orders larger than indicated quantity, please check with WOS.

Part Number		A	B	L	SNBHE		SNBHES	
Type	No.				Unit Price Qty. 1 ~ 9	Volume Discount Rate 10~20	Unit Price Qty. 1 ~ 9	Volume Discount Rate 10~20
SNBHE SNBHES	1S	50.5	43.5	36.8				
	1.5S	50.5	43.5	44.7				
	2S	64.0	56.5	52.6				
	2.5S	77.5	70.5	63.0				
	3S	91.0	83.5	73.6				

For orders larger than indicated quantity, please check with WOS.

Part Number		A	B	H	SNBT		SNBTS	
Type	No.				Unit Price Qty. 1 ~ 9	Volume Discount Rate 10~20	Unit Price Qty. 1 ~ 9	Volume Discount Rate 10~20
SNBTS	8A	34.0	27.5	55	-	-		
	10A				-	-		
	15A				-	-		
SNBT SNBTS	1S	50.5	43.5	55				
	1.5S	50.5	43.5	70				
	2S	64.0	56.5	82				
	2.5S	77.5	70.5	105				
	3S	91.0	83.5	110				

For orders larger than indicated quantity, please check with WOS.

Part Number		A <sub>1</sub>	B <sub>1</sub>	H <sub>1</sub>	A <sub>2</sub>	B <sub>2</sub>	H <sub>2</sub>	Unit Price
Type	No.							Qty. 1 ~ 5
SNBTD	1.5S-1S	50.5	43.5	70.0	50.5	43.5	66.0	
	2S-1S	64.0	56.5	82.0	50.5	43.5	72.0	
	2S-1.5S	64.0	56.5	82.0	50.5	43.5	85.0	
	2.5S-1.5S	77.5	70.5	105.0	50.5	43.5	91.0	
	2.5S-2S	77.5	70.5	105.0	64.0	56.5	103.0	

For orders larger than indicated quantity, please check with WOS.



Ordering Example

Part Number - L  
 SNPAA1S - 150  
 SNBES8A  
 SNBTD2S-1S



Example

