


Note that, for some of the types shown here, order might be unable to be received by the MISUMI Malaysia, Indonesia and/or India offices.

Miniature Couplings

Barbed Couplers



SRTG BOX-SRTG (50 pcs. / pack)

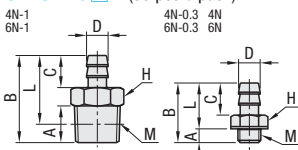


M Material: Brass (for M3 thread, free-cutting steel)
S Surface Treatment: Electroless Nickel Plating
A Accessory: Gasket: SUS304, NBR (M3, M5)

Hose Nipples



SRTN BOX-SRTN (50 pcs. / pack)

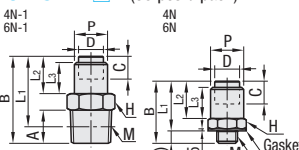

M Material: Brass
S Surface Treatment: Electroless Nickel Plating
A Accessory: Gasket: SUS304, NBR (M5 only)

Part Number Type	No.	Tube I.D. (mm)	Tube O.D. (mm)	M	A	B	L	C	Width Across H (mm)	Mass (g)	Effective Sectional Area (mm ²)	Unit Price 1 ~ 49 pc(s)	Volume Discount Rate (50 pcs. / pack)
SRTG BOX-SRTG	4N-0.3	2.5	4	M3x0.5	2.5	12	9.5	5.5	0.8	0.9			
	6N-0.3	4	6	M3x0.5	2.5	12	10	5.5	1.3	0.9			
	4N	2.5	4	M5x0.8	3	13	10	7	1.5	1.7			
	6N	4	6	M5x0.8	3	13	10	7	1.5	3.8			
	4N-1	2.5	4	R1 / 8	8	19	15	10	1.9	1.7			
	6N-1	4	6	R1 / 8	8	19	15	10	7.5	3.8			


Part Number Type	No.	Tube I.D. (mm)	Tube O.D. (mm)	M	A	B	C	L ₁	L ₂	L ₃	P	Width Across H (mm)	Mass (g)	Effective Sectional Area (mm ²)	Unit Price 1 ~ 49 pc(s)	Volume Discount Rate (50 pcs. / pack)
SRTN BOX-SRTN	4N	2.5	4	M5x0.8	3	14.5	5	11.5	8.5	7	6.5	7	2.5	2		
	6N	4	6	M5x0.8	3	15	5.5	12	9	7.5	8	8	3.4	3.8		
	4N-1	2.5	4	R1 / 8	8	20.5	5	16.5	8.5	7	6.5	10	7.9	2		
	6N-1	4	6	R1 / 8	8	21	5.5	17	9	7.5	8	10	8.9	3.8		

When SRT□N-1 is selected, seal adhesive is applied to thread portion.
 For combination with a tube, select the same number as that of the tube O.D.

Nipples



MNPLN

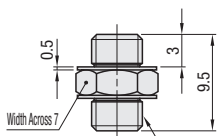


M Material: Brass
S Surface Treatment: Electroless Nickel Plating
A Accessory: Gasket: SUS304, NBR

Elbows



MELBN

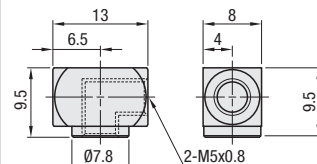


M Material: Brass
S Surface Treatment: Electroless Nickel Plating

Plugs



MPLGN

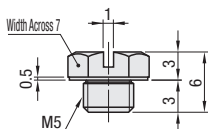


M Material: Brass
S Surface Treatment: Electroless Nickel Plating
A Accessory: Gasket: SUS304, NBR

Tees



MTEN

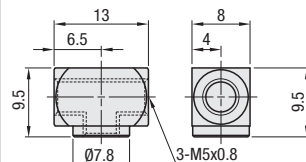


M Material: Brass
S Surface Treatment: Electroless Nickel Plating

Bushings



MBSGN

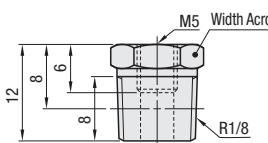


M Material: Brass
S Surface Treatment: Electroless Nickel Plating
 Seal adhesive is applied to R1/8 thread portion.

Universal Tees



MUTEN

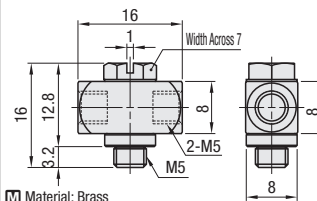

M Material: Brass
S Surface Treatment: Electroless Nickel Plating
A Accessory: Gasket: Polyacetal

Part Number	Effective Sectional Area (mm ²)	Mass (g)	Unit Price 1 ~ 49 pc(s)	Volume Discount Rate 50 ~ 100
MNPLN	3.9	1.5		
MPLGN	-	1.5		
MBSGN	12	5.7		
MELBN	-	5.5		
MTEN	-	5.5		
MUTEN	1.5	6.5		



Ordering Example

Part Number
SRTG4N
BOX-SRTG4N

Specifications (SRTG)

Applicable Fluid	Air
Max. Operating Pressure	0.5MPa
Operating Vacuum Level	-100kPa
Operating Temperature Range	0~50°C

(SRTN, MNPLN, MELBN, MPLGN, MTEN, MBSGN, MUTEN)

Applicable Fluid	Air
Max. Operating Pressure	1MPa
Operating Vacuum Level	-100kPa
Operating Temperature Range	0~50°C