


 
Adjustable Hoses Components / Installation Tools







Hose (Blue)

RoHS 10

HJD




Part Number		Number of Links	Hose I.D.	D	B	L1	Unit Price
Type	Hose Nominal						1 ~ 20 pc(s).
HJD	2	5	6.3	15.9	14.8	20.3	
	3		8.5	20.2	17.6	25.2	
	4		12.7	25.1	21.1	29.8	


Connector Only (Orange)

RoHS 10


■ **Male Threaded AAJD**

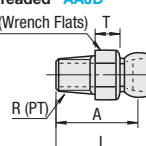


■ **Male Valve AVAD**

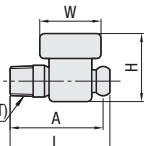


■ **Female Valve AVAFD**

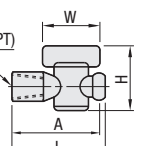

■ **L-Shaped AAJL**

 

■ **Y-Shaped AAJY**

 


Part Number		Connector Thread Size R (PT)	A	L	H	T	Unit Price
Type	Hose Nominal						1 ~ 20 pc(s).
AAJD	2	1 (R1/8)	23	26.3	14	7	
	3	2 (R1/4)	27.3	32	19	8	
		4 (R1/2)					
	4	3 (R3/8)	28	38.3	18.8	7.5	
		4 (R1/2)			20.8		

Part Number		Connector Thread Size R (PT)	A	L	H	W	Unit Price
Type	Hose Nominal						1 ~ 20 pc(s).
AVAD	2	2 (R1/4)	41	41	30	27	
	3	3 (R3/8)	45	45	34	25	
	4	4 (R1/2)	48.5	48.5	43	34	

Part Number		Connector Thread Size R (PT)	A	L	H	W	Unit Price
Type	Hose Nominal						1 ~ 20 pc(s).
AVAFD	2	2 (Rc1/4)	42	45	30	27	
	4	4 (Rc1/2)	58.2	64	63	34	


Part Number		AAJL		AAJY		Unit Price 1 ~ 20 pc(s).	
Type	Hose Nominal	L2	L3	L4	L5	AAJY	AAJL
AAJL (L-Shaped)	2	17	12	15.5	9.5		
AAJY (Y-Shaped)	4	23.5	16.5	23.5	19		



Nozzle Only (Orange)
(Photo is for Shape A)

RoHS 10


HAKD
(Drawing is for Shape A)

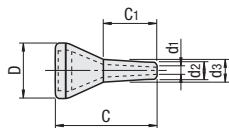

For dimension details, see P1478.

Part Number		Nozzle		Unit Price 1 ~ 20 pc(s).				
Type	Hose Nominal	Shape	No.	Shape A	Shape B	Shape C	Shape D	Shape M
HAKD	2	A B C D M	1					
			2				-	
			3				-	
	3		1		-	-	-	
			2		-	-	-	
			3		-	-	-	
	4		1			-	-	-
			2			-	-	-
			3			-	-	-

Ordering Example	Part Number	-	Number of Links	Part Number	-	Nozzle	Part Number	-	Connector Thread Size
	HJD2	-	5	HAKD2	-	A1	AAJD2	-	1



Special Mounting Tool for Adjustable Hose

RoHS 10

Part Number	No.	Unit Price
HOSAJT	2	
	3	
	4	

For dimension details, see P1478.

For dimension details, see P1478.

Can be used for both installation and removal.

Ordering Example	Part Number
	HOSAJT2

