

Floating Joints - Quick Connection Type

[Tapped] Cylinder Connector and Holder Set/Sheet Metal Holder Set

■ **Features:** Purchasing a set of Connector (FJR) and Holder (HLRA) for Floating Joints Quick Connection Type is better value than purchasing stand-alone products.


Cylinder Connector and Holder Set



RoHS10

Type	Holder Type	Material	Surface Treatment	Hardness
FJRHA	HLRA	S45C Equivalent	Salt-bath Nitriding	500HV~

- ⚠ Salt-bath Nitriding may cause uneven color, which doesn't affect mechanical function.
- 🔍 For details of Salt-bath Nitriding, see P.1907.

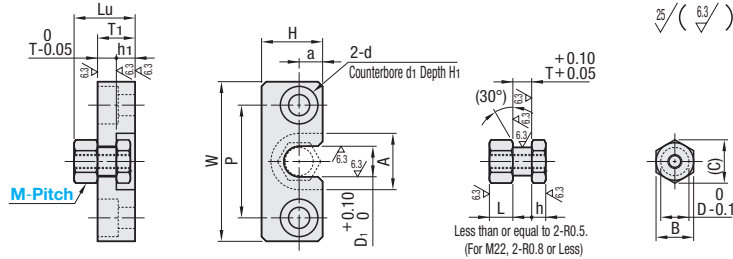

Type	Part Number	Cylinder Connector						Holder											Unit Price	
		M-Pitch	T	D	L	h	B	C	D1	A	T1	h1	W	H	a	P	d	d1		H1
FJRHA	3-0.5	4	6	5	3	8	9.2	6.5	12	8	4	34	13	5	24	4.5	8	4.4	13	
	4-0.7	4	7	6	3	10	11.5	8	14	8	4	36	15	6	26	4.5	8	4.4	14	
	5-0.8	6	8	7	3	12	13.9	9	17	10	4	42	18	7	30	5.5	9.5	5.4	17	
	6-1.0	6	10	8	4	14	16.2	11	19	11	5	44	20	8	32	5.5	9.5	5.4	19	
	8-1.25	8	13	9	4	17	19.6	14	23	13	5	52	24	10	38	6.6	11	6.5	22	
	10-1.25	8	16	11	4	21	24.2	18	28	13	5	56	30	12	42	6.6	11	6.5	24	
	14-1.5	12	21	13	4	26	30	23	34	17	5	70	36	15	52	9	14	8.6	30	
18-1.5	15	25	15	5	30	34.6	27	38	21	6	84	43	19	62	11	17	10.5	36		



Ordering Example **Part Number**
FJRHA5-0.8


Sheet Metal Holder Set




RoHS10

Type	Material		Surface Treatment	Hardness
	Floating Joints	Holder		
FJSC	S45C Equivalent	SPOC Equivalent	Salt-bath Nitriding	500HV~

Joint

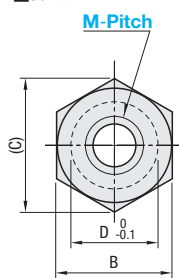

Included Holder

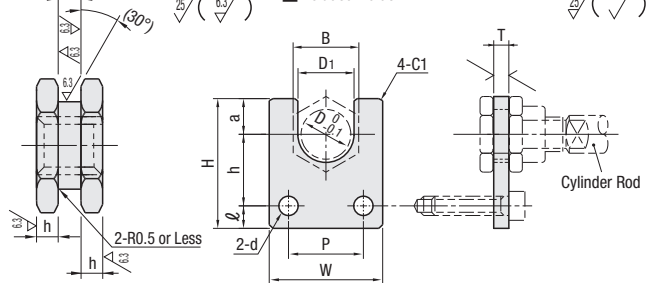

- ⚠ Salt-bath Nitriding may cause uneven color, which doesn't affect mechanical function.
- 🔍 For details of Salt-bath Nitriding, see P.1907.

Type	Part Number	M-Pitch	T	Cylinder Connector				Included Holder											Unit Price
				Tolerance	h	D	B	(C)	T	Tolerance	B	D1	W	H	a	h	ℓ	P	
FJSC	3-0.5	2.3	+0.3 +0.25	2	6	8	9.2	2.3	±0.19	8	6.5	16	25	5	14	6	8	4.5	19
	4-0.7	2.3	+0.3 +0.25	2	7	10	11.5	2.3	±0.19	10	8	19	26	6	14	6	10	4.5	54
	5-0.8	3.2	+0.35 +0.3	3	8	12	13.9	3.2	±0.23	12	9	22	33	7	18	8	12	5.5	123
	6-1.0	3.2	+0.35 +0.3	3	10	14	16.2	3.2	±0.23	14	11	25	34	8	18	8	14	5.5	123



Ordering Example **Part Number**
FJSC4-0.7

