
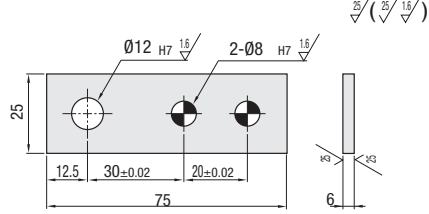


Hinge Plates

■ Features: Economical Square Type and Flexible Dimension R Type are available.

■ Square

HPAN

RoHS 10


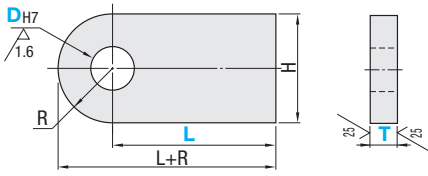
Material: Steel for General Structure

Part Number	Unit Price
HPAN	

Ordering Example: Part Number HPAN

■ Type R

HPE

 



Material: SS400

Part Number	D	L 10mm Increment	T Selection	R	H	Unit Price
HPE	8	40~100	9 12 15 16	11	22	
	10			12.5	25	
	12			16	32	
	16			19	38	
	20			25	50	


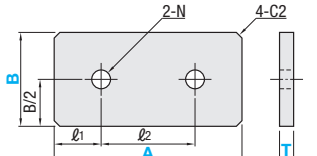
Ordering Example: Part Number HPE12 - L 100 - T 16

Alterations: Part Number HPE12 - L 100 - T 16 - (WCC) WCC10

Alterations	Code	Spec.
	WCC	The corners on both sides can be cut in any given length. WCC=1mm Increment 1 ≤ WCC < H/2

■ Economy Type

Type	Material	Surface Treatment
JNPB	SPCC	Trivalent Bright Chromate
JNPS	SUS304	-

RoHS 10

Part Number	A	B	T		l1	l2	N	Unit Price			
			JNPB	JNPS				JNPB	JNPS	T2.0	T4.5
JNPB	30	10 20	2.0	2.0	5	4.5	20				
	40	10 20 30						30			
	50	10 20 30 40						40			
JNPS	60	10 20 30 40 50	4.5	4.0	10	5.5	30				
	70	10 20 30 40 50						40			
	80	10 20 30 40 50						50			
	90	10 20 30 40 50						60			
	100	10 20 30 40 50						60			

Ordering Example: Part Number JNPB50 - B 30 - T 2.0