

# Flat Bar


## Cold-Rolled Square Flat Steel Bars



RoHS10

Type	Part Number	Material
Flat Steel	FSS	SS400D
	FSC	S45CD
	FSSS	SUS304D
	FSSA	A6063S

6.3  
32 (6.3/)

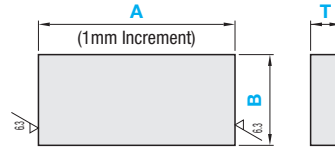

(Ex.) For FSS-250-32-9

A Dimension x Area Unit Price = Price

### FSS (Material: SS400D) Price

A: 1mm Increment	T	B	5	6	9	10	12	16	19	22	25	30
30~ 50	16								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	22								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	25								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	32								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	38								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	50								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	60		-						-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	75		-						-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	100		-						-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	125		-		-				-	-	-	-
51~ 150			-		-				-	-	-	-
151~ 300			-		-				-	-	-	-
301~ 800			-		-				-	-	-	-

### FSC (Material: S45CD) Price

A: 1mm Increment	T	B	5	6	9	12	16	19	22	25	30	
30~ 50	16								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	22								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	25								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	32								-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	38								-	-	-	-
51~ 150									-	-	-	-
151~ 300									-	-	-	-
301~ 800									-	-	-	-
30~ 50	50								-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	60								-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	75								-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	100								-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-
30~ 50	125								-	-	-	-
51~ 150			-						-	-	-	-
151~ 300			-						-	-	-	-
301~ 800			-						-	-	-	-