


# Economy Panel Clamps

Points to compare against Similar Products | By adopting PVC as the material, economical pricing has been achieved.

For the similar products, see P815

## Economy Panel Clamps

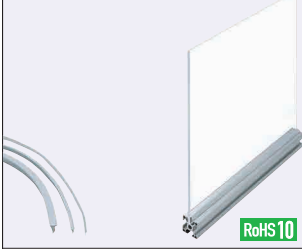

• For 5mm Thickness Panel

 
**5 Series**  
**NSCP1H**

S (Light Gray)




**6 Series**  
**NSCP3H**

S (Light Gray)



**8, 8-45 Series**  
**NSCP5H**

 S (Light Gray)



Type	Color	Material	Heat Resistant Temp.
NSCP	Light Gray	PVC	-25~80°C

• For 3mm Thickness Panel

 
**5 Series**  
**NSCP3H**

S (Light Gray)




**6 Series**  
**NSCP5HN**

S (Light Gray)



**8, 8-45 Series**  
**NSCP7H**

 S (Light Gray)



• NSCP3H serves to fix 5 Series Aluminum Extrusions as well as 6 Series ones.  
• HSCP uses the other material than HSCP (P815) and thus, differs from HSCP in the color tone of Light Gray. In addition, on the lower part of the back surface of these two part number products, the thin groove is machined to distinguish between them.

## Standard Length

Part Number		Color	Length m	Applicable Extrusion (Series)	Applicable Panel Thickness	Length 6m		Length 12m	
Type	No.					Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
						1 ~ 8 pc(s).	9~50	1 ~ 8 pc(s).	9~50
NSCP	1H	S (Light Gray)	6	5 Series	5				
	3H				3				
	5HN				5				
	5H				3				
	7H				5				
			12	8-45 Series	3				

Ordering Example: Part Number - Color - Length  
**NSCP3H - S - 12**

## How to select Panel Clamps and Economy Panel Clamps (App. Example)

Panel Plate Thickness 5mm			
Extrusion	HFS5	HFS6	HFS8 HFS8-45
Drawing	HSCP1H HSCP1H NSCP1H 	HSCP3H HSCP3H NSCP3H 	HSCP5H HSCP5H NSCP5H 
Panel Plate Thickness 3mm			
Extrusion	HFS5	HFS6	HFS8 HFS8-45
Drawing	HSCP3H HSCP3H NSCP3H 	HSCP5HN HSCP5HN NSCP5HN 	HSCP7H HSCP7H NSCP7H 

**ex** Example

Can be cut to any length with scissors, a utility knife, etc. Better appearance will be obtained if the corner is cut at 45°.

<After Assembly>

